
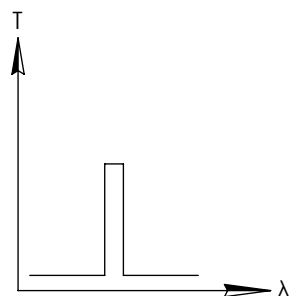
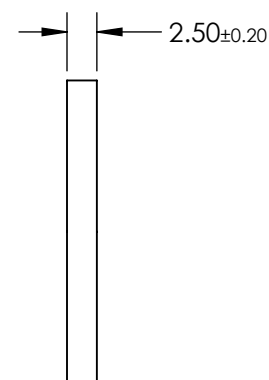
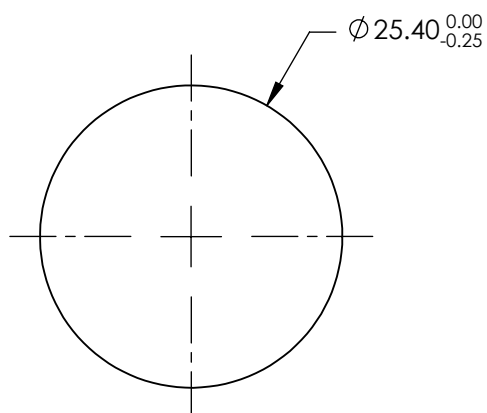


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

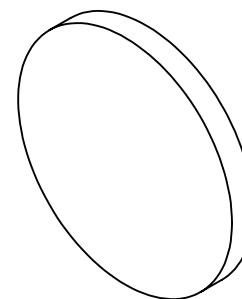

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	340
FULL WIDTH HALF MAX (FWHM) (nm)	85
SURFACE QUALITY	80-50
COATING TYPE	VIS 0° (425-675nm)
BEVEL	PROTECTIVE AS NEEDED



ALL DIMS IN mm

**Edmund Optics®**

TITLE

HOYA U-340 (UV) 25.4mm Dia., VIS 0° Coated, Colored  
Glass Bandpass Filter

DWG NO

36307

SHEET  
1 OF 1