
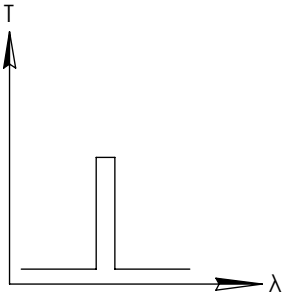
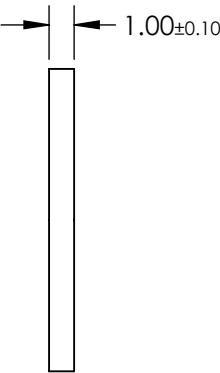
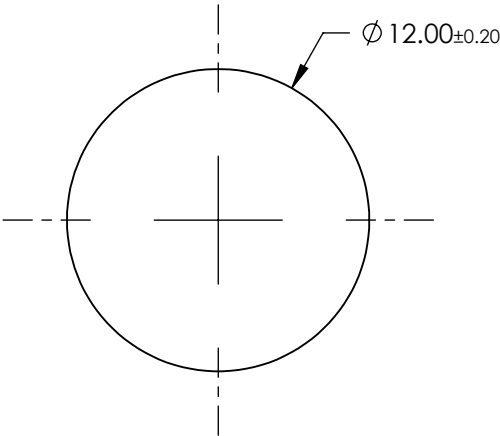


NOTE:

1. SUBSTRATE: COLORED GLASS

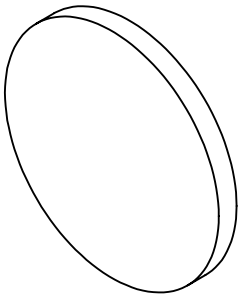

BANDPASS FILTER


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	390.00
FULL WIDTH HALF MAX (FWHM) (nm)	125.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED



ALL DIMS IN mm

 Edmund Optics®			
TITLE		Hoya B390 (UVVIS) 12mm Dia., 1mm Thick, Colored Glass Bandpass Filter	
DWG NO		18781	SHEET 1 OF 1